


A3081605-1 Cut Sheet

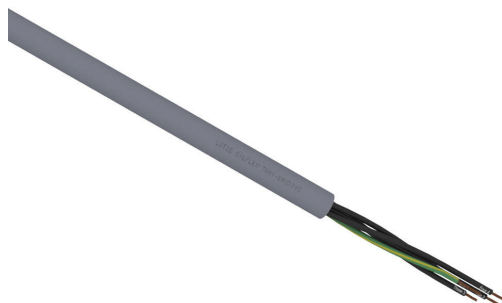

LUTZE Silflex flexible control cable, unshielded, 5 conductors (includes ground), 16 AWG, bare copper, PVC/Nylon conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A3081605-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Series	Silflex
Wire/Cable Type	Control
UL Wire/Cable Type	TC, TC-ER, WTTC and MTW
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V (Types TC, TC-ER, MTW), 1000V (Type WTTC)
Conductors	5 conductors (includes ground)
Conductor Size	16 AWG
Conductor Stranding	26-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon
Conductor Insulation Color	Black with white numbers and green/yellow ground

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.377in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 75ft = Coil• 76 to 275ft = 14 x 7in Reel• 276 to 390ft = 14 x 10in Reel• 391 to 600ft = 16 x 10in Reel• 601 to 840ft = 18 x 10in Reel• 841 to 1090ft = 18 x 13in Reel• 1091 to 2445ft = 24 x 17in Wooden Reel• 2446 to 3910ft = 30 x 17in Wooden Reel• 3911 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E324630
UL Recognized File #	none
UL Hazardous File #	none
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement