


A3081804-1 Cut Sheet

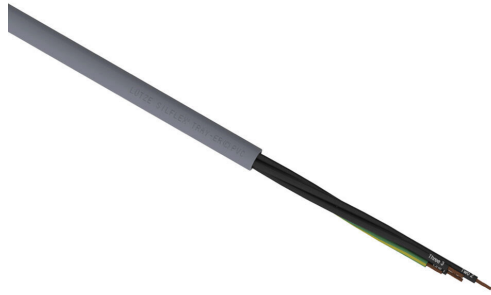

LUTZE Silflex flexible control cable, unshielded, 4 conductors (includes ground), 18 AWG, bare copper, PVC/Nylon conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A3081804-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Series	Silflex
Wire/Cable Type	Control
UL Wire/Cable Type	TC, TC-ER, WTTC and MTW
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V (Types TC, TC-ER, MTW), 1000V (Type WTTC)
Conductors	4 conductors (includes ground)
Conductor Size	18 AWG
Conductor Stranding	19-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon
Conductor Insulation Color	Black with white numbers and green/yellow ground

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.32in
Bulk Length	Cut to length
Package Type	1 to 75ft = Coil, 76 to 380ft = 14 x 7in Reel, 381 to 540ft = 14 x 10in Reel, 541 to 840ft = 16 x 10in Reel, 841 to 1190ft = 18 x 10in Reel, 1191 to 1540ft = 18 x 13in Reel, 1541 to 3320ft = 24 x 17in Wooden Reel, 3321 to 5470ft = 30 x 17in Wooden Reel, 5471 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E324630
UL Recognized File #	none
UL Hazardous File #	none
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement