


A3081805-1 Cut Sheet

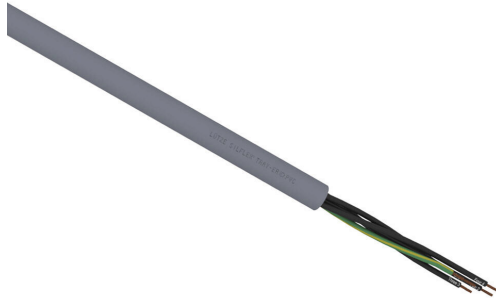

LUTZE Silflex flexible control cable, unshielded, 5 conductors (includes ground), 18 AWG, bare copper, PVC/Nylon conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A3081805-1>

Technical Specifications

Brand	LUTZE	Shielding	Unshielded
Item	Cable	Jacket Material	PVC
Series	Silflex	Jacket Color	Gray
Wire/Cable Type	Control	Nominal Overall Cable Diameter	0.346in
UL Wire/Cable Type	TC, TC-ER, WTTC and MTW	Bulk Length	Cut to length
Application	General purpose	Package Type	<ul style="list-style-type: none">• 20 to 75ft = Coil• 76 to 325ft = 14 x 7in Reel• 326 to 465ft = 14 x 10in Reel• 466 to 715ft = 16 x 10in Reel• 716 to 995ft = 18 x 10in Reel• 996 to 1295ft = 18 x 13in Reel• 1296 to 2900ft = 24 x 17in Wooden Reel• 2901 to 4640ft = 30 x 17in Wooden Reel• 4641 to 5000ft = Large Wooden Reel
Flexibility	Flexible		
Voltage Rating	600V (Types TC, TC-ER, MTW), 1000V (Type WTTC)		
Conductors	5 conductors (includes ground)		
Conductor Size	18 AWG		
Conductor Stranding	19-stranded		
Conductor Material	Bare copper		
Conductor Insulation Material	PVC/Nylon		
Conductor Insulation Color	Black with white numbers and green/yellow ground		

Agency Approvals

UL Listed File #	E324630
UL Recognized File #	none
UL Hazardous File #	none
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement