


A3081809-1 Cut Sheet

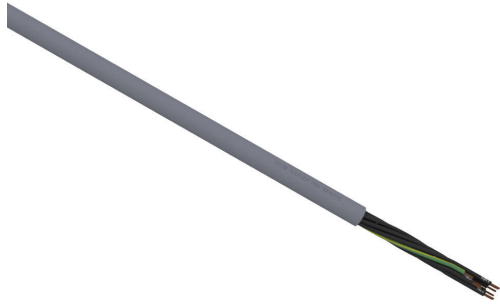

LUTZE Silflex flexible control cable, unshielded, 9 conductors (includes ground), 18 AWG, bare copper, PVC/Nylon conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A3081809-1>

Technical Specifications

Brand	LUTZE	Conductor Insulation Color	Black with white numbers and green/yellow ground
Item	Cable	Shielding	Unshielded
Series	Silflex	Jacket Material	PVC
Wire/Cable Type	Control	Jacket Color	Gray
UL Wire/Cable Type	TC, TC-ER, WTTC and MTW	Nominal Overall Cable Diameter	0.425in
Application	General purpose	Bulk Length	Cut to length
Flexibility	Flexible	Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 215ft = 14 x 7in Reel• 216 to 310ft = 14 x 10in Reel• 311 to 475ft = 16 x 10in Reel• 476 to 660ft = 18 x 10in Reel• 661 to 860ft = 18 x 13in Reel• 861 to 1920ft = 24 x 17in Wooden Reel• 1921 to 2500ft = 30 x 17in Wooden Reel
Voltage Rating	600V (Types TC, TC-ER, MTW), 1000V (Type WTTC)		
Conductors	9 conductors (includes ground)		
Conductor Size	18 AWG		
Conductor Stranding	19-stranded		
Conductor Material	Bare copper		
Conductor Insulation Material	PVC/Nylon		

Agency Approvals

UL Listed File #	E324630
UL Recognized File #	none
UL Hazardous File #	none
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement