


A3082007-1 Cut Sheet

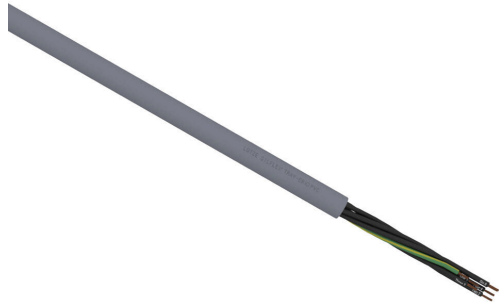

LUTZE Silflex flexible control cable, unshielded, 7 conductors (includes ground), 20 AWG, bare copper, PVC/Nylon conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A3082007-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Series	Silflex
Wire/Cable Type	Control
UL Wire/Cable Type	PLTC-ER, ITC-ER and MTW
Application	General purpose
Flexibility	Flexible
Voltage Rating	300V (Types PLTC-ER, ITC-ER), 600V (Type MTW)
Conductors	7 conductors (includes ground)
Conductor Size	20 AWG
Conductor Stranding	10-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon
Conductor Insulation Color	Black with white numbers and green/yellow ground

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.335in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 75ft = Coil• 76 to 345ft = 14 x 7in Reel• 346 to 495ft = 14 x 10in Reel• 496 to 760ft = 16 x 10in Reel• 761 to 1065ft = 18 x 10in Reel• 1066 to 1385ft = 18 x 13in Reel• 1386 to 3095ft = 24 x 17in Wooden Reel• 3096 to 4950ft = 30 x 17in Wooden Reel• 4951 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E324630
UL Recognized File #	none
UL Hazardous File #	none
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement