


A3092007-1 Cut Sheet

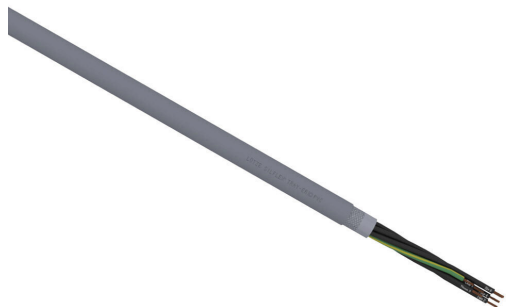

LUTZE Silflex flexible control cable, shielded, 7 conductors (includes ground), 20 AWG, bare copper, PVC/Nylon conductor insulation material, black with white numbers and green/yellow ground, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A3092007-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Series	Silflex
Wire/Cable Type	Control
UL Wire/Cable Type	PLTC-ER, ITC-ER and MTW
Application	General purpose
Flexibility	Flexible
Voltage Rating	300V (Types PLTC-ER, ITC-ER), 600V (Type MTW)
Conductors	7 conductors (includes ground)
Conductor Size	20 AWG
Conductor Stranding	10-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon
Conductor Insulation Color	Black with white numbers and green/yellow ground

Shielding	Shielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.36in
Bulk Length	Cut to length
Package Type	1 to 75ft = Coil, 76 to 300ft = 14 x 7in Reel, 301 to 430ft = 14 x 10in Reel, 431 to 660ft = 16 x 10in Reel, 661 to 940ft = 18 x 10in Reel, 941 to 1220ft = 18 x 13in Reel, 1221 to 2520ft = 24 x 17in Wooden Reel, 2521 to 4320ft = 30 x 17in Wooden Reel, 4321 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E324630
UL Recognized File #	none
UL Hazardous File #	none
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement