


A3160804-1 Cut Sheet

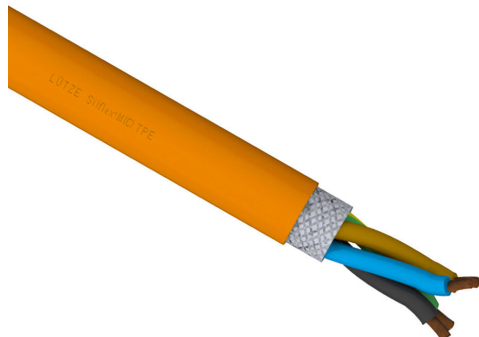

LUTZE Silflex flexible servo cable, shielded, 4 conductors (includes ground), 8 AWG, bare copper, PVC/Nylon conductor insulation material, brown, black, blue and green/yellow ground, TPE jacket, orange, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A3160804-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Series	Silflex
Wire/Cable Type	Servo
UL Wire/Cable Type	TC-ER and WTTC
Applicable Standards	UL 2277
Application	Drive and motor
Flexibility	Flexible
Voltage Rating	600V (Type TC-ER), 1000V (Type WTTC, Flexible Motor Supply Cable)
Conductors	4 conductors (includes ground)
Conductor Size	8 AWG
Conductor Stranding	168-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon

Conductor Insulation Color	Brown, black, blue and green/yellow ground
Shielding	Tinned copper braid
Jacket Material	TPE
Jacket Color	Orange
Nominal Overall Cable Diameter	0.825in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 30ft = Coil• 31 to 55ft = 14 x 7in Reel• 56 to 80ft = 14 x 10in Reel• 81 to 125ft = 16 x 10in Reel• 126 to 175ft = 18 x 10in Reel• 176 to 230ft = 18 x 13in Reel• 231 to 510ft = 24 x 17in Wooden Reel• 511 to 815ft = 30 x 17in Wooden Reel• 816 to 1000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E352875
UL Recognized File #	E197090
UL Hazardous File #	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement