


A3161404-1 Cut Sheet

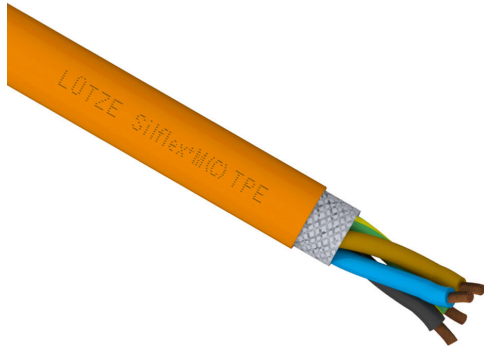

LUTZE Silflex flexible servo cable, shielded, 4 conductors (includes ground), 14 AWG, bare copper, PVC/Nylon conductor insulation material, brown, black, blue and green/yellow ground, TPE jacket, orange, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A3161404-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Series	Silflex
Wire/Cable Type	Servo
UL Wire/Cable Type	TC-ER and WTTC
Applicable Standards	UL 2277
Application	Drive and motor
Flexibility	Flexible
Voltage Rating	600V (Type TC-ER), 1000V (Type WTTC, Flexible Motor Supply Cable)
Conductors	4 conductors (includes ground)
Conductor Size	14 AWG
Conductor Stranding	41-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon

Conductor Insulation Color	Brown, black, blue and green/yellow ground
Shielding	Tinned copper braid
Jacket Material	TPE
Jacket Color	Orange
Nominal Overall Cable Diameter	0.455in
Bulk Length	Cut to length
Package Type	1 to 50ft = Coil, 51 to 190ft = 14 x 7in Reel, 191 to 270ft = 14 x 10in Reel, 271 to 415ft = 16 x 10in Reel, 416 to 575ft = 18 x 10in Reel, 576 to 750ft = 18 x 13in Reel, 751 to 1675ft = 24 x 17in Wooden Reel, 1676 to 2685ft = 30 x 17in Wooden Reel, 2686 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E352875
UL Recognized File #	E197090
UL Hazardous File #	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement