


A3171004-1 Cut Sheet

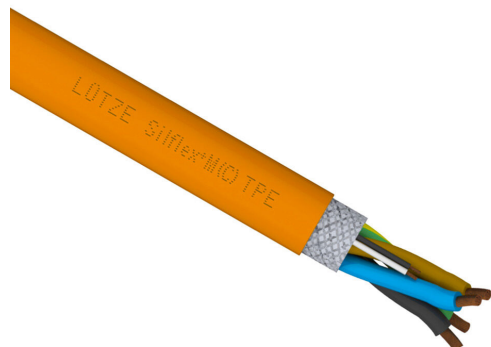

LUTZE Silflex flexible servo cable, shielded, 4 conductors (includes ground), 10 AWG, bare copper, (1) shielded 18 AWG twisted pair, PVC/Nylon conductor insulation material, brown, black, blue and green/yellow ground, TPE jacket, orange, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A3171004-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Series	Silflex
Wire/Cable Type	Servo
UL Wire/Cable Type	TC-ER and WTTC
Applicable Standards	UL 2277
Application	Drive and motor
Flexibility	Flexible
Voltage Rating	600V (Type TC-ER), 1000V (Type WTTC, Flexible Motor Supply Cable)
Conductors	4 conductors (includes ground)
Conductor Size	10 AWG
Conductor Stranding	105-stranded
Conductor Material	Bare copper
Auxiliary Conductors	(1) shielded 18 AWG twisted pair
Conductor Insulation Material	PVC/Nylon

Conductor Insulation Color	Brown, black, blue and green/yellow ground
Shielding	Tinned copper braid
Jacket Material	TPE
Jacket Color	Orange
Nominal Overall Cable Diameter	0.716in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 75ft = 14 x 7in Reel• 76 to 110ft = 14 x 10in Reel• 111 to 165ft = 16 x 10in Reel• 166 to 235ft = 18 x 10in Reel• 236 to 305ft = 18 x 13in Reel• 306 to 675ft = 24 x 17in Wooden Reel• 676 to 1085ft = 30 x 17in Wooden Reel• 1086 to 2500ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E352875
UL Recognized File #	E197090
UL Hazardous File #	None
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement