


A3251807-1 Cut Sheet

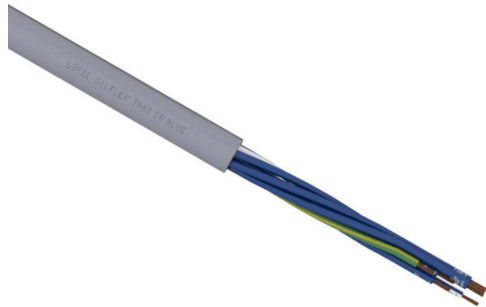

LUTZE Silflex flexible control cable, unshielded, 7 conductors (includes ground), 18 AWG, bare copper, PVC/Nylon conductor insulation material, blue with white numbers and green/yellow ground, #2 conductor is white/blue, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A3251807-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Series	Silflex
Wire/Cable Type	Control
UL Wire/Cable Type	TC-ER and MTW
Application	24VDC (NFPA 79)
Flexibility	Flexible
Voltage Rating	600V (Types TC-ER, MTW)
Conductors	7 conductors (includes ground)
Conductor Size	18 AWG
Conductor Stranding	19-stranded
Conductor Material	Bare copper
Conductor Insulation Material	PVC/Nylon
Conductor Insulation Color	Blue with white numbers and green/yellow ground, #2 conductor is white/blue

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.37in
Bulk Length	Cut to length
Package Type	1 to 75ft = Coil, 76 to 280ft = 14 x 7in Reel, 281 to 400ft = 14 x 10in Reel, 401 to 610ft = 16 x 10in Reel, 611 to 870ft = 18 x 10in Reel, 871 to 1130ft = 18 x 13in Reel, 1131 to 2430ft = 24 x 17in Wooden Reel, 2431 to 4000ft = 30 x 17in Wooden Reel, 4001 to MAX = Large Wooden Reel

Agency Approvals

UL Listed File #	E197091
UL Recognized File #	none
UL Hazardous File #	none
CSA File #	LL41103
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement