


A6012012-1 Cut Sheet

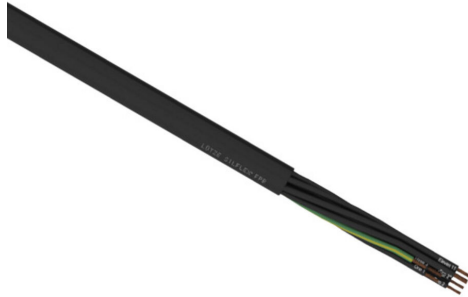

LUTZE Silflex FBP flexible control cable, unshielded, 12 conductors (includes ground), 20 AWG, bare copper, polypropylene conductor insulation material, black with white numbers and green/yellow ground, TPE jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A6012012-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Series	Silflex FBP
Wire/Cable Type	Control
UL Wire/Cable Type	AWM
Applicable Standards	UL 20886 and ECOLAB
Application	Food and beverage
Flexibility	Flexible
Voltage Rating	1000V
Conductors	12 conductors (includes ground)
Conductor Size	20 AWG
Conductor Stranding	10-stranded
Conductor Material	Bare copper

Conductor Insulation Material	Polypropylene
Conductor Insulation Color	Black with white numbers and green/yellow ground
Shielding	Unshielded
Jacket Material	TPE
Jacket Color	Black
Nominal Overall Cable Diameter	0.339in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 75ft = Coil• 76 to 340ft = 14 x 7in Reel• 341 to 485ft = 14 x 10in Reel• 486 to 745ft = 16 x 10in Reel• 746 to 1000ft = 18 x 10in Reel

Agency Approvals

UL Listed File #	none
UL Recognized File #	E197090
UL Hazardous File #	none
CSA File #	None
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement