


A6061004-1 Cut Sheet

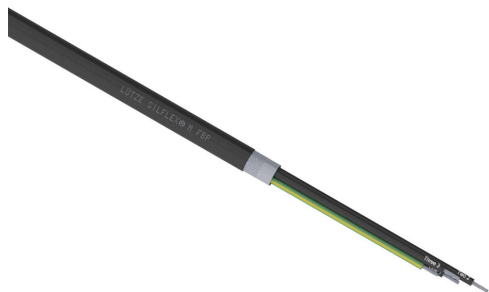

LUTZE Silflex FBP VFD cable, overall foil and braid shielded, 4 conductors (includes ground), 10 AWG, tinned copper, XLPE conductor insulation material, black with white numbers and green/yellow ground, TPE jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A6061004-1>

Technical Specifications

Brand	LUTZE	Shielding	Overall foil and braid shielded
Item	Cable	Jacket Material	TPE
Series	Silflex FBP	Jacket Color	Black
Wire/Cable Type	VFD	Nominal Overall Cable Diameter	0.194in
Applicable Standards	AWM 20886 and ECOLAB	Bulk Length	Cut to length
Application	Drive and motor and food and beverage	Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 90ft = 14 x 7in Reel• 91 to 130ft = 14 x 10in Reel• 131 to 200ft = 16 x 10in Reel• 201 to 280ft = 18 x 10in Reel• 281 to 365ft = 18 x 13in Reel• 366 to 815ft = 24 x 17in Wooden Reel• 816 to 1305ft = 30 x 17in Wooden Reel• 1306 to 2500ft = Large Wooden Reel
Flexibility	Flexible		
Voltage Rating	1000V		
Conductors	4 conductors (includes ground)		
Conductor Size	10 AWG		
Conductor Stranding	105-stranded		
Conductor Material	Tinned copper		
Conductor Insulation Material	Cross linked polyethylene (XLPE)		
Conductor Insulation Color	Black with white numbers and green/yellow ground		

Agency Approvals

UL Recognized File #	E197090
CE	View CE declarations
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document