


A6061404-1 Cut Sheet

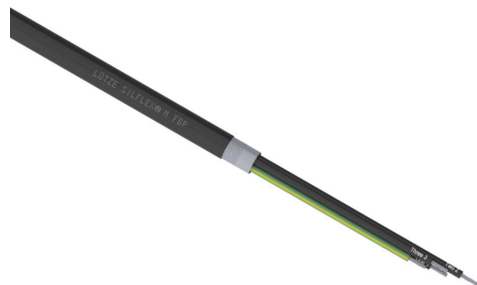

LUTZE Silflex FBP VFD cable, overall foil and braid shielded, 4 conductors (includes ground), 14 AWG, tinned copper, XLPE conductor insulation material, black with white numbers and green/yellow ground, TPE jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A6061404-1>

Technical Specifications

Brand	LUTZE
Item	Cable
Series	Silflex FBP
Wire/Cable Type	VFD
Applicable Standards	AWM 20886 and ECOLAB
Application	Drive and motor and food and beverage
Flexibility	Flexible
Voltage Rating	1000V
Conductors	4 conductors (includes ground)
Conductor Size	14 AWG
Conductor Stranding	41-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	Cross linked polyethylene (XLPE)
Conductor Insulation Color	Black with white numbers and green/yellow ground

Shielding	Overall foil and braid shielded
Jacket Material	TPE
Jacket Color	Black
Nominal Overall Cable Diameter	0.138in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 185ft = 14 x 7in Reel• 186 to 260ft = 14 x 10in Reel• 261 to 400ft = 16 x 10in Reel• 401 to 560ft = 18 x 10in Reel• 561 to 725ft = 18 x 13in Reel• 726 to 1625ft = 24 x 17in Wooden Reel• 1626 to 2500ft = 30 x 17in Wooden Reel

Agency Approvals

UL Recognized File #	E197090
CE	View CE declarations
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document