


# A6061604-1 Cut Sheet

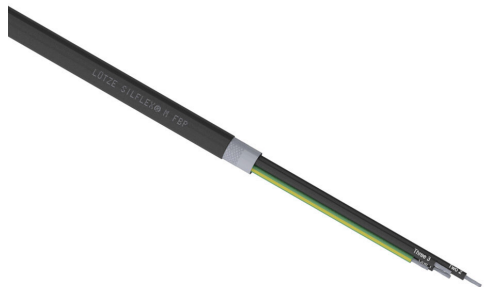

LUTZE Silflex FBP VFD cable, overall foil and braid shielded, 4 conductors (includes ground), 16 AWG, tinned copper, XLPE conductor insulation material, black with white numbers and green/yellow ground, TPE jacket, black, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A6061604-1>

## Technical Specifications

<b>Brand</b>	LUTZE
<b>Item</b>	Cable
<b>Series</b>	Silflex FBP
<b>Wire/Cable Type</b>	VFD
<b>Applicable Standards</b>	AWM 20886 and ECOLAB
<b>Application</b>	Drive and motor and food and beverage
<b>Flexibility</b>	Flexible
<b>Voltage Rating</b>	1000V
<b>Conductors</b>	4 conductors (includes ground)
<b>Conductor Size</b>	16 AWG
<b>Conductor Stranding</b>	26-stranded
<b>Conductor Material</b>	Tinned copper
<b>Conductor Insulation Material</b>	Cross linked polyethylene (XLPE)
<b>Conductor Insulation Color</b>	Black with white numbers and green/yellow ground

<b>Shielding</b>	Overall foil and braid shielded
<b>Jacket Material</b>	TPE
<b>Jacket Color</b>	Black
<b>Nominal Overall Cable Diameter</b>	0.123in
<b>Bulk Length</b>	Cut to length
<b>Package Type</b>	<ul style="list-style-type: none"><li>• 20 to 50ft = Coil</li><li>• 51 to 215ft = 14 x 7in Reel</li><li>• 216 to 305ft = 14 x 10in Reel</li><li>• 306 to 470ft = 16 x 10in Reel</li><li>• 471 to 660ft = 18 x 10in Reel</li><li>• 661 to 855ft = 18 x 13in Reel</li><li>• 856 to 1915ft = 24 x 17in Wooden Reel</li><li>• 1916 to 2500ft = 30 x 17in Wooden Reel</li></ul>

## Agency Approvals

<b>UL Recognized File #</b>	E197090
<b>CE</b>	<a href="#">View CE declarations</a>
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>