


A61600 Cut Sheet

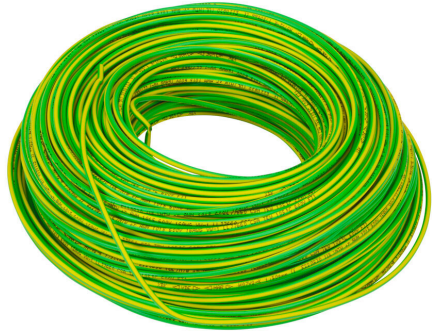

LUTZE HAR H07V-K hook-up wire, single conductor, 16 AWG (1.50mm²), 30-stranded, tinned copper, PVC conductor insulation material, green/yellow, 450/750V (H07V2-K), 600V (MTW), 328ft carton.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/A61600>

Technical Specifications

Brand	LUTZE
Item	Wire
Wire/Cable Type	HAR H07V-K
UL Wire/Cable Type	AWM, MTW and HAR
Applicable Standards	UL 1015, UL 1063 and UL 1581
Application	Hook-up
Flexibility	Flexible
Voltage Rating	450/750V (H07V2-K), 600V (MTW)
Conductors	Single conductor
Conductor Size	16 AWG (1.50mm ²)
Conductor Stranding	30-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Green/yellow
Bulk Length	328ft carton

Agency Approvals

UL Listed File #	E220830
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	LL77660
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document