


# ACT800-42L-S Cut Sheet

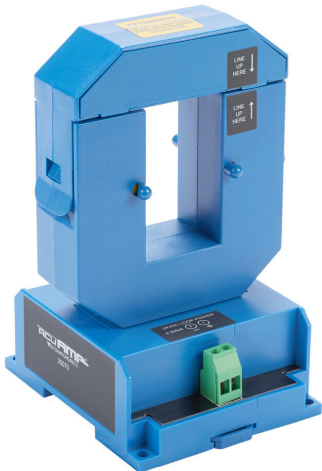

AcuAMP AC current transducer, 1-phase, split core, 0-800A sensing range, 4-20mA output.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/ACT800-42L-S>

## Technical Specifications

Brand	AcuAMP
Item	AC Current transducer
Number of Phases	1
Body Type	Split core
Sensing Range	0-800A
True RMS	No
Output	4-20mA
Operating Voltage	24 VDC
Mounting	Panel or 35mm DIN rail
Electrical Connection	Screw terminals
UL Rating	UL 508 listed

## Agency Approvals

UL Listed File #	E197592
UL Recognized File #	None
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>