


# ACTH005-42-24-S Cut Sheet

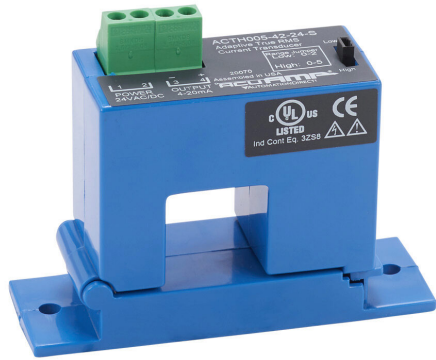

AcuAMP AC current transducer, 1-phase, split core, 0-2, 0-5A selectable, with time integration sensing range, True RMS, 4-20mA output.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/ACTH005-42-24-S>

## Technical Specifications

<b>Brand</b>	AcuAMP
<b>Item</b>	AC Current transducer
<b>Number of Phases</b>	1
<b>Body Type</b>	Split core
<b>Sensing Range</b>	0-2, 0-5A selectable, with time integration
<b>True RMS</b>	Yes
<b>Output</b>	4-20mA
<b>Operating Voltage</b>	24 VAC/VDC
<b>Mounting</b>	Panel or optional 35mm DIN rail
<b>Electrical Connection</b>	Screw terminals
<b>UL Rating</b>	UL 508 listed

## Agency Approvals

<b>UL Listed File #</b>	E197592
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>