


# ACTH050-42-24-S Cut Sheet

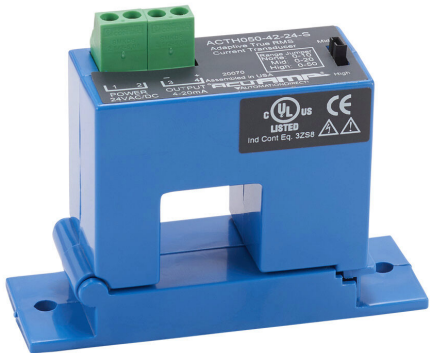

AcuAMP AC current transducer, 1-phase, split core, 0-10, 0-20, 0-50A selectable, with time integration sensing range, True RMS, 4-20 mA output.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/ACTH050-42-24-S>

## Technical Specifications

Brand	AcuAMP
Item	Current transducer
Voltage Type	AC
Number of Phases	1
Body Type	Split core
Sensing Range	0-10, 0-20, 0-50A selectable, with time integration
True RMS	Yes
Output	4-20 mA
Operating Voltage	24 VAC/VDC
Mounting	Panel or optional 35mm DIN rail
Electrical Connection	Screw terminals
UL Rating	UL 508 listed

## Agency Approvals

UL Listed File #	E197592
UL Recognized File #	None
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/ACTH050-42-24-S.pdf>  
See store item page for other formats.