


AD03010 Cut Sheet

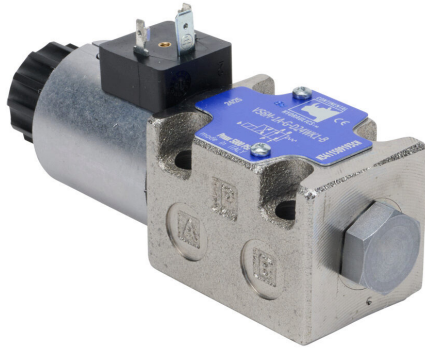

Continental hydraulic solenoid valve, D03, 4-port (4-way), 2-position, single solenoid spring return, cast iron body, momentary manual override, 23.2 GPM, 24 VDC, 31W, 18mm DIN style wiring plug.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/AD03010>

Technical Specifications

Brand	Continental	Flow Capacity	23.2 GPM
Item	Valve	Maximum Operating Pressure	5000 psi
Working Fluid	Petroleum based hydraulic fluid	Minimum Operating Pressure	0 psi
Valve Type	Solenoid directional control	Working Fluid Temperature	-4 to +176 °F
Port Quantity	4-port (4-way)	Operating Voltage	24 VDC
Number Of Positions	2	Power Rating	31W
Action	Single solenoid spring return	Electrical Connection	18mm DIN style wiring plug
Body Material	Cast iron	Form Factor	D03
Seal Material	Viton	Includes	O-rings and mounting hardware
Mounting	Subplate or manifold	Manufacturer Part Number	VS6M-1A-G-D24WK1
Manual Override Type	Momentary		

Agency Approvals

UL Listed File #	None
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/AD03010.pdf>
See store item page for other formats.