


ADM100C-LP Cut Sheet

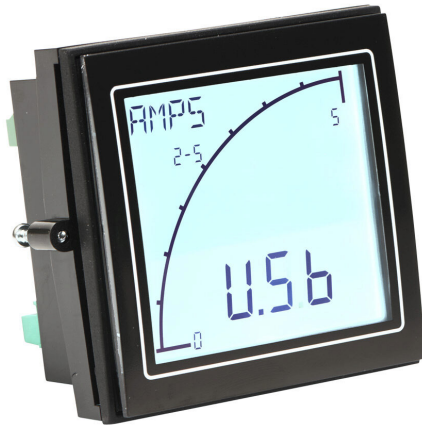

Trumeter ADM100 standard graphical current meter, current input, 3in positive backlit LCD configurable to white, green, red, (2) discrete or current outputs, 12-24 VAC/VDC operating voltage.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/ADM100C-LP>

Technical Specifications

Brand	Trumeter	Operating Voltage	12-24 VAC/VDC
Item	Graphical current meter	Accuracy	0.5%
Series	ADM100	NEMA Rating	4
Application	Standard	IP Rating	IP65
Display Type	3in positive backlit LCD configurable to white, green, red	Mounting	Panel
Input Current Signal Range	0-5A	Mounting Hole Size	68 x 68mm (2.68 x 2.68in)
Discrete Output Type	Open collector (34 VDC/0.5A)	Additional Information	Configurable using the free downloadable utility software. User customizable display parameters are static or based on alarm threshold: scaling, blinking, color, intensity, 4 digit alphanumeric message
Output Current Signal Range	4-20 mA		

Agency Approvals

UL Listed File #	E469787
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/ADM100C-LP.pdf>
See store item page for other formats.