


ADP2T5100Z11 Cut Sheet

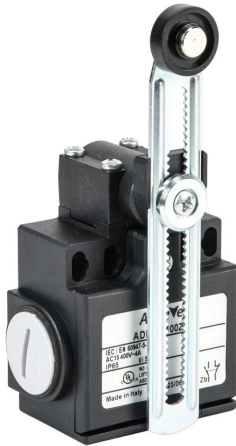

AchieVe IEC limit switch, side rotary 2mm step adjustable lever with 18mm nylon roller, 90-degree adjustable head, (1) N.O./ (1) N.C. contact(s), snap action, 20-22mm or 40-42mm hole spacing, plastic, (2) PG11 cable entries with (1) 1/2in NPT adapter.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/ADP2T5100Z11>

Technical Specifications

Brand	AchieVe
Item	Limit switch
Switch Type	IEC
Actuator Type	Side rotary 2mm step adjustable lever with 18mm nylon roller
Head Type	90-degree adjustable
Contact Type	(1) N.O./ (1) N.C.
Action	Snap action
Reset	No

Body Width	50mm
Mounting Hole Spacing	20-22mm or 40-42mm
Material	Plastic
IP Rating	IP66
Operating Temperature	-25 to 70 deg C
Connection	(2) PG11 cable entries with (1) 1/2in NPT adapter
Halogen Free	No

Agency Approvals

UL Listed File #	NKCR.E191072
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/ADP2T5100Z11.pdf>
See store item page for other formats.