


BBV1200-ADC Cut Sheet

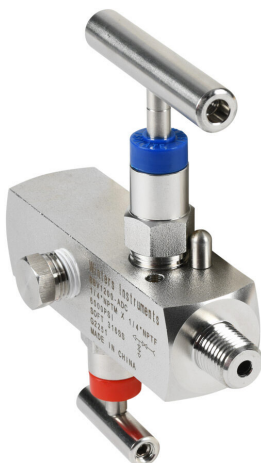

Winters manual block and bleed needle valve, straight body soft seat, double handles, stainless steel body, 1/4in male NPT inlet(s), 1/4in female NPT outlet(s).

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/BBV1200-ADC>

Technical Specifications

Brand	Winters
Item	Needle valve
Valve Type	Manual block and bleed
Form Factor	Straight body soft seat
Operator Type	Double handles
Body Material	Stainless steel
Inlet Port	1/4in male NPT
Outlet Port	1/4in female NPT
Operating Pressure	6,000 psi @ 212°F
Operating Temperature	32°F to 383°F (0°C to 195°C)

Agency Approvals

CE	None
RoHS Status	No
EU REACH	View EU REACH document