


# BDSR43 Cut Sheet

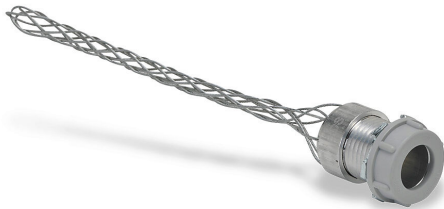

Bryant dust-tight strain relief grip, accepts cable diameter size 0.43 to 0.54in, 1/2in NPS male thread fitting, galvanized steel mesh, 4.75in length, indoor applications only. Steel locknut and insulating bushing included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/BDSR43>

## Technical Specifications

Brand	Bryant
Item	Cord grip
Grip Type	Strain relief
Application	Dust-tight
Low Tension	No
Cable Diameter Size	0.43 to 0.54in
Thread Size	1/2in NPS male thread fitting
Mesh Material	Galvanized steel
Mesh Length	4.75in
Environmental Requirements	Indoor applications only
Includes	Steel locknut and insulating bushing

## Agency Approvals

UL Listed File #	E167220
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	701228
RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/BDSR43.pdf>  
See store item page for other formats.