


BDSR97 Cut Sheet

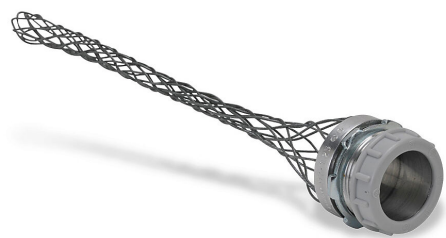

Bryant dust-tight strain relief grip, accepts cable diameter size 0.97 to 1.25in, 1-1/4in NPS male thread fitting, galvanized steel mesh, 9in length, indoor applications only. Steel locknut and insulating bushing included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/BDSR97>

Technical Specifications

Brand	Bryant
Item	Cord grip
Grip Type	Strain relief
Application	Dust-tight
Low Tension	No
Cable Diameter Size	0.97 to 1.25in
Thread Size	1-1/4in NPS male thread fitting
Mesh Material	Galvanized steel
Mesh Length	9in
Environmental Requirements	Indoor applications only
Includes	Steel locknut and insulating bushing

Agency Approvals

UL Listed File #	E167220
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	701228
RoHS Status	No
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/BDSR97.pdf>
See store item page for other formats.