


BFMT-18N Cut Sheet

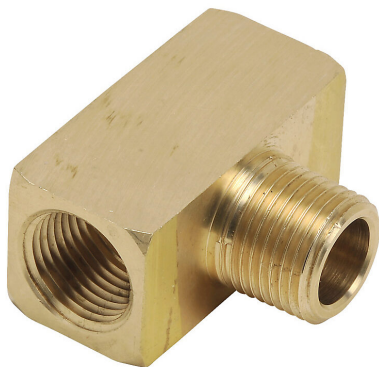

NITRA pneumatic threaded fitting, tee, brass body, (1) 1/8in male NPT to (2) 1/8in female NPT. Package of 2.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/BFMT-18N>

Technical Specifications

| | |
|---------------------------|--|
| Brand | NITRA |
| Item | Pneumatic Threaded Fitting |
| Fitting Type | Tee |
| Body Material | Brass |
| Connection | (1) 1/8in male NPT to (2) 1/8in female NPT |
| Operating Pressure | 800 psi |
| Quantity per Pack | 2 |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | None |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | None |
| RoHS Status | No |
| EU REACH | View EU REACH document |