


BM3RHB-020 Cut Sheet

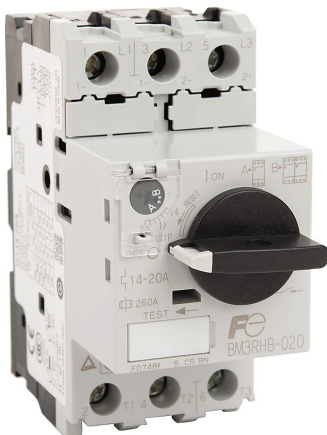

Fuji Electric BM3R series manual motor protector, rotary, 20A, thermal overload, 14.0-20.0A adjustable, 260A instantaneous trip rating, open, 45mm frame.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/BM3RHB-020>

Technical Specifications

Brand	Fuji Electric	Power Poles	(3) N.O.
Series	BM3R	Trip Class	Trip Class 10
Item	Motor protector	Phase Loss Sensitive	Yes
Starter Type	Manual	Ground Fault Protection	No
Actuator Type	Rotary	SCCR Rating	50kA SCCR
Amperage Rating	20A	UL Rating	UL 508 rated
Voltage Rating	600 VAC	Enclosure Type	Open
Horsepower Rating	10hp	Frame	45mm
Relay Type	Thermal overload	Mounting	35mm DIN rail
Operation Type	Bi-metallic	Connection	Screw terminal
Full Load Amperage Range	14.0-20.0A adjustable	Additional Information	For UL Type E listing, terminal cover BZ0TCRE and Short Circuit Alarm contact block BZ0TKUAB must be added to the MMS. Suitable as a motor disconnect
Instantaneous Trip Rating	260A		
Number of Poles	3		

Agency Approvals

UL Listed File #	E211710
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document