


BMEHG1-02-L Cut Sheet

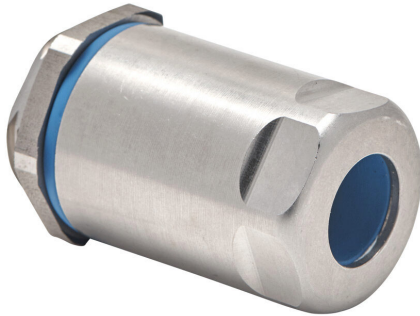

Bimed hygienic EMC cable gland, M20 x 1.5mm thread type, stainless steel, accepts 6 to 12mm diameter cable, IP66, IP68 and IP69. Mounting hardware included. Allen wrench size 13mm, use adapter BMFGT-03 to reduce Allen wrench size to 8mm.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/BMEHG1-02-L>

Technical Specifications

Brand	Bimed
Item	Cable gland
Application	Hygienic EMC
Thread Type	M20 x 1.5mm
Material	Stainless steel
Cable OD Range	6 to 12mm
Shield OD Range	5 to 11mm
IP Rating	IP66, IP68 and IP69
UL Type	1, 2, 4, 4X, 12, 12K and 13
Strain Relief	No
Includes	Mounting hardware
Additional Information	Allen wrench size 13mm, use adapter BMFGT-03 to reduce Allen wrench size to 8mm

Agency Approvals

UL Listed File #	E199260
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/BMEHG1-02-L.pdf>
See store item page for other formats.