


BN4040403 Cut Sheet

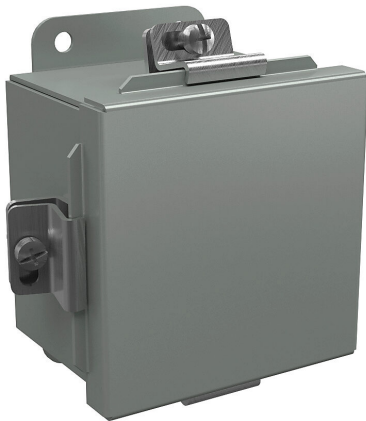

Wiegmann enclosure, NEMA 4/12/13, 4 x 4 x 3in (HxWxD), wall mount, carbon steel, ANSI 61 gray, powder coat finish, lift-off cover, (4) stainless steel clamps.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/BN4040403>

Technical Specifications

Brand	Wiegmann
Item	Enclosure
Slope Top	No
3-Piece Assembly	No
Vented	No
NEMA Rating	4/12/13
IP Rating	IP66
Nominal Enclosure Dimensions	4 x 4 x 3in (HxWxD)
Enclosure Height	4.31in
Enclosure Width	4.31in
Enclosure Depth	3.16in
Mounting	Wall
Integral Mounting Feet	No

Integral Mounting Flange	Yes
Dual Access	No
Knockouts	No
Bottom Gland Plate	No
Material	Carbon steel
Color	ANSI 61 gray
Finish	Powder coat
Cover Type	Lift-off cover
Latch Type	(4) stainless steel clamps
Shelf	No
Padlockable	No
Keylocking	No

Agency Approvals

UL Listed File #	E23553, E64791
UL Recognized File #	None
UL Hazardous File #	None
CE	None
CSA File #	None
RoHS Status	No
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/BN4040403.pdf>
See store item page for other formats.