


BP4SWA Cut Sheet

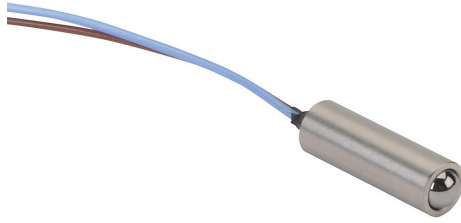

Metrol limit switch, precision touch, 4mm diameter, smooth, 12.8mm length, 3mm head, tungsten carbide, ball plunger, 1N contact force, N.O. contact(s), 1.6ft/0.5m cable length, core wire.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/BP4SWA>

Technical Specifications

| | |
|------------------------------|-----------------|
| Brand | Metrol |
| Item | Limit switch |
| Switch Type | Precision touch |
| Diameter | 4mm |
| Barrel Type | Smooth |
| Length | 12.8mm |
| Head Type | 3mm |
| Actuator Type | Ball plunger |
| Contact Force | 1N |
| Contact Type | N.O. |
| Cable Length | 1.6ft/0.5m |
| Connection | Core wire |
| Conductor Size | 28 AWG |
| Stroke | 0.8mm |
| Repeatability | 0.01mm |
| Material | Stainless steel |
| IP Rating | IP40 |
| Operating Temperature | 0 to 80 deg C |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | None |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | None |
| CSA File # | None |
| RoHS Status | No |
| EU REACH | View EU REACH document |