


BR-N1-15K0W04P2 Cut Sheet

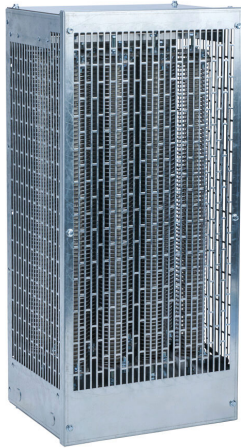

Crohm braking resistor, 15 kW, 4.2 ohm, NEMA 1, built-in temperature switch. For use with multiple AC drives.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/BR-N1-15K0W04P2>

Technical Specifications

| | |
|------------------------------------|--------------------|
| Brand | Crohm |
| Item | Braking resistor |
| Brake Resistor Power Rating | 15 kW |
| Resistance | 4.2 ohm |
| Enclosure Type | NEMA 1 |
| Built-in Temperature Switch | Yes |
| For Use With | Multiple AC drives |

Agency Approvals

| | |
|-----------------------------|---------------------------------------------------------------------|
| UL Listed File # | None |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | 303117 |
| RoHS Status | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| EU REACH | View EU REACH document |
| Other | RoHS Statement |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/BR-N1-15K0W04P2.pdf>
See store item page for other formats.