


# BX-06RTD Cut Sheet

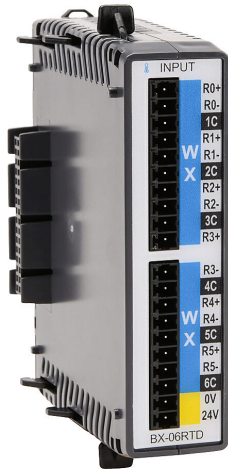

BRX temperature input module, RTD, 6-channel, 16-bit resolution, input RTD type(s): Pt100, JPt100, Cu10, Cu25, Pt1000 and Ni120. (1) BX-RTB10 screw terminal block kit included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/BX-06RTD>

## Technical Specifications

|                                   |   |
|-----------------------------------|---|
| <b>Brand</b>                      | BRX   |
| <b>Item</b>                       | Input module  |
| <b>I/O Module Type</b>            | Temperature   |
| <b>Input Signal Type(s)</b>       | RTD   |
| <b>Number Of Channels</b>         | 6   |
| <b>Input RTD Signal Types</b>     | Pt100, JPt100, Cu10, Cu25, Pt1000 and Ni120   |
| <b>Input Resolution</b>           | 16-bit  |
| <b>External Power Requirement</b> | 24 VDC  |
| <b>Includes</b>                   | (1) BX-RTB10 screw terminal block kit   |
| <b>Programming Software</b>       | Do-more Designer programming software v2.3 or later   |
| <b>Additional Information</b>     | Optional BX-RTB10-1 or BX-RTB10-2 terminal block kits sold separately. Pre-wired ZIPLinks not available for temperature modules |

## Agency Approvals

|                             |  |
|-----------------------------|--|
| <b>UL Listed File #</b>     | E139594                                |
| <b>UL Recognized File #</b> | None                                   |
| <b>UL Hazardous File #</b>  | None                                   |
| <b>CE</b>                   | <a href="#">View CE declarations</a>   |
| <b>CSA File #</b>           | None                                   |
| <b>RoHS Status</b>          | Yes (See CE Doc)                       |
| <b>EU REACH</b>             | <a href="#">View EU REACH document</a> |