


BX-06RTD Cut Sheet

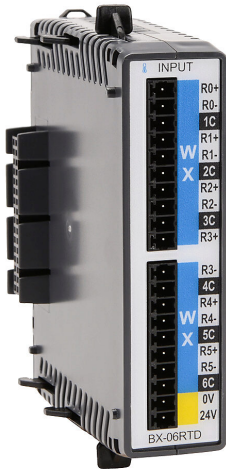

BRX temperature input module, RTD, 6-channel, 16-bit resolution, input RTD type(s): Pt100, JPt100, Cu10, Cu25, Pt1000 and Ni120. (1) BX-RTB10 screw terminal block kit included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/BX-06RTD>

Technical Specifications

Brand	BRX
Item	Input module
I/O Module Type	Temperature
Input Signal Type(s)	RTD
Number Of Channels	6
Input RTD Signal Types	Pt100, JPt100, Cu10, Cu25, Pt1000 and Ni120
Input Resolution	16-bit
External Power Requirement	24 VDC
Includes	(1) BX-RTB10 screw terminal block kit
Programming Software	Do-more Designer programming software v2.3 or later
Additional Information	Optional BX-RTB10-1 or BX-RTB10-2 terminal block kits sold separately. Pre-wired ZIPLinks not available for temperature modules

Agency Approvals

UL Listed File #	E139594
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/BX-06RTD.pdf>
See store item page for other formats.