


BX-P-SER2-TERMFC Cut Sheet

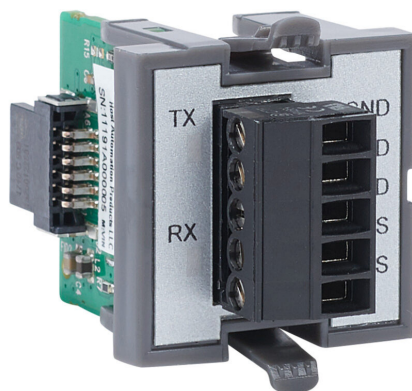

BRX communication POM module, Do-more protocol, Modbus RTU and ASCII, 1 port, buffered, (1) RS-232 (5-pin terminal) port(s). For use with all BRX MPUs. BX-RTB05S terminal block included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/BX-P-SER2-TERMFC>

Technical Specifications

| | |
|--|---|
| Brand | BRX |
| Item | Communication POM module |
| Number of Ports | 1 |
| Buffered Ports | Yes |
| Communication Port and Connection Type(s) | (1) RS-232 (5-pin terminal) |
| Port Protocol(s) | <ul style="list-style-type: none">• Do-more protocol• Modbus RTU Slave• ASCII In/out• K-sequence Slave |
| Port Speed(s) | up to 115.2k baud |
| For Use With | All BRX MPUs |
| Includes | BX-RTB05S terminal block |
| Programming Software | Do-more Designer programming software v2.7 or later |
| Additional Information | Optional RTS/CTS hardware flow control |

Agency Approvals

| | |
|-----------------------------|--|
| UL Listed File # | E185989 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |