


BX-SERIO-2 Cut Sheet

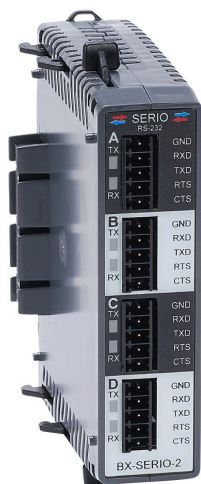

BRX communication module, Do-more protocol, Modbus RTU and ASCII, 4 ports, buffered, (4) RS-232 (5-pin terminal) port(s). For use with all BRX MPUs. (4) BX-RTB05S terminal blocks included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/BX-SERIO-2>

Technical Specifications

Brand	BRX
Item	Communication module
Number of Ports	4
Buffered Ports	Yes
Communication Port and Connection Type(s)	(4) RS-232 (5-pin terminal)
Port Protocol(s)	<ul style="list-style-type: none">• Do-more protocol• Modbus RTU Master/Slave• ASCII In/out• K-sequence Slave
Port Speed(s)	up to 115.2k baud
For Use With	All BRX MPUs
Includes	(4) BX-RTB05S terminal blocks
Programming Software	Do-more Designer programming software v2.7 or later
Additional Information	Optional RTS/CTS hardware flow control

Agency Approvals

UL Listed File #	E185989
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document