


# C0-04DA-2 Cut Sheet

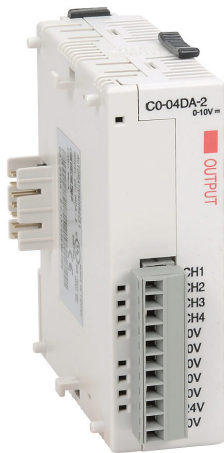

CLICK analog output module, 4-channel, voltage, 12-bit, output voltage signal range(s) of 0-10 VDC, external 24 VDC required.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/C0-04DA-2>

## Technical Specifications

<b>Brand</b>	CLICK
<b>Item</b>	Output module
<b>I/O Module Type</b>	Analog
<b>Number Of Output Channels</b>	4
<b>Output Signal Type</b>	Voltage
<b>Analog Output Type</b>	Sourcing
<b>Isolated Channels</b>	No

<b>Output Resolution</b>	12-bit
<b>Output Voltage Signal Range</b>	0-10 VDC
<b>External Power Requirement</b>	24 VDC
<b>Includes</b>	Removable terminal block
<b>Programming Software</b>	CLICK programming software v1.40 or later and CLICK CPU firmware v1.40 or later

## Agency Approvals

<b>UL Listed File #</b>	E157382
<b>UL Recognized File #</b>	None
<b>UL Hazardous File #</b>	None
<b>CE</b>	<a href="#">View CE declarations</a>
<b>CSA File #</b>	None
<b>RoHS Status</b>	Yes (See CE Doc)
<b>EU REACH</b>	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/C0-04DA-2.pdf>  
See store item page for other formats.