


C0-04TRS-10 Cut Sheet

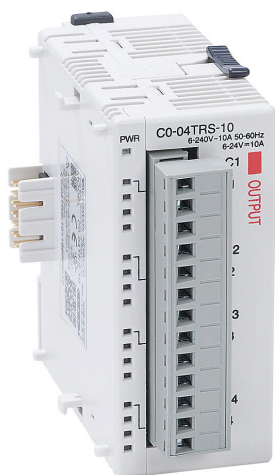

CLICK relay output module, 4-point, 6-24 VDC/6-240 VAC, (4) Form A (SPST) no-suppression, 4 isolated common(s), 1 point(s) per common, 10A/point. Removable terminal block included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/C0-04TRS-10>

Technical Specifications

Brand	CLICK
Item	Output module
I/O Module Type	Relay
Number of Output Points	4
Nominal Output Voltage	6-24 VDC/6-240 VAC
Relay Configuration	(4) Form A (SPST) no-suppression relays
Number of Isolated Commons	4
Jumper Selectable Isolation	No
Number of Points per Common	1
Load Current	10A/point
Fuse Type	User-supplied external fuse
Includes	Removable terminal block
Programming Software	CLICK programming software v2.60 or later and CLICK CPU firmware v2.60 or later

Agency Approvals

UL Listed File #	E157383
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document