


C0-08TD2 Cut Sheet

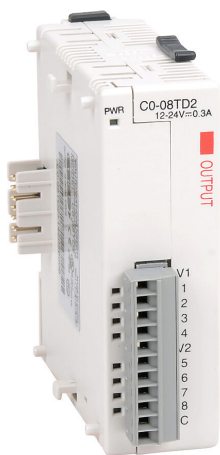

CLICK discrete output module, 8-point, 12-24 VDC, sourcing,
1 isolated common(s), 8 point(s) per common, 0.3A/point.
Removable terminal block included.

For complete product information, please see this item on our
store at the following link:



<https://www.automationdirect.com/pn/C0-08TD2>

Technical Specifications

| | |
|-----------------------------------|---------------|
| Brand | CLICK |
| Item | Output module |
| I/O Module Type | Discrete |
| Number of Output Points | 8 |
| Nominal Output Voltage | 12-24 VDC |
| Discrete Output Type | Sourcing |
| Number of Isolated Output Commons | 1 |

| | |
|-----------------------------|---|
| Number of Points per Common | 8 |
| Load Current | 0.3A/point |
| Fuse Type | User-supplied external fuse |
| Includes | Removable terminal block |
| Programming Software | CLICK programming software v1.00 or later and CLICK CPU firmware v1.00 or later |

Agency Approvals

| | |
|----------------------|--|
| UL Listed File # | E157382 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CE | View CE declarations |
| CSA File # | None |
| RoHS Status | Yes (See CE Doc) |
| EU REACH | View EU REACH document |

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/C0-08TD2.pdf>
See store item page for other formats.