


C0-08TR-3 Cut Sheet

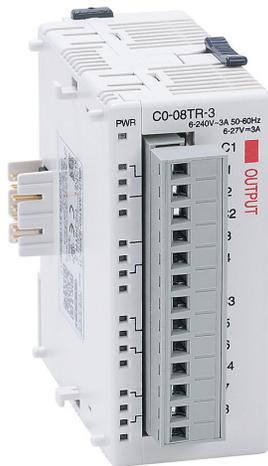

CLICK relay output module, 8-point, 6-27 VDC/6-240 VAC, (8) Form A (SPST) no-suppression, 4 isolated common(s), 2 point(s) per common, 3A/point. Removable terminal block included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/C0-08TR-3>

Technical Specifications

Brand	CLICK
Item	Output module
I/O Module Type	Relay
Number of Output Points	8
Nominal Output Voltage	6-27 VDC/6-240 VAC
Relay Configuration	(8) Form A (SPST) no-suppression relays
Number of Isolated Commons	4
Jumper Selectable Isolation	No

Number of Points per Common	2
Load Current	3A/point
Fuse Type	User-supplied external fuse
Includes	Removable terminal block
Programming Software	CLICK programming software v2.60 or later and CLICK CPU firmware v2.60 or later

Agency Approvals

UL Listed File #	E157382
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/C0-08TR-3.pdf>
See store item page for other formats.