


C0-16TD1 Cut Sheet

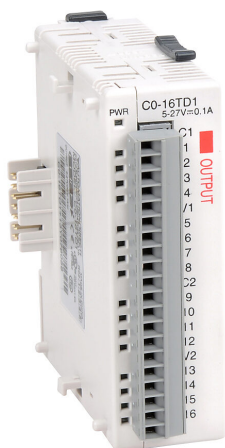

CLICK discrete output module, 16-point, 5-27 VDC, sinking, 2 isolated common(s), 8 point(s) per common, 0.1A/point. Removable terminal block included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/C0-16TD1>

Technical Specifications

Brand	CLICK
Item	Output module
I/O Module Type	Discrete
Number of Output Points	16
Nominal Output Voltage	5-27 VDC
Discrete Output Type	Sinking
Number of Isolated Output Commons	2

Number of Points per Common	8
Load Current	0.1A/point
Fuse Type	User-supplied external fuse
Includes	Removable terminal block
Programming Software	CLICK programming software v1.00 or later and CLICK CPU firmware v1.00 or later

Agency Approvals

UL Listed File #	E157382
UL Recognized File #	None
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/C0-16TD1.pdf>
See store item page for other formats.