


# C0-16TD2 Cut Sheet

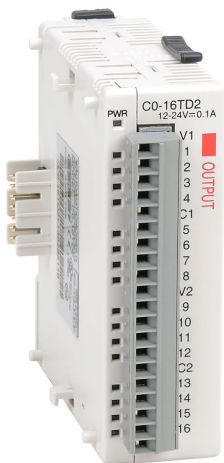

CLICK discrete output module, 16-point, 12-24 VDC, sourcing, 2 isolated common(s), 8 point(s) per common, 0.1A/point. Removable terminal block included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/C0-16TD2>

## Technical Specifications

Brand	CLICK
Item	Output module
I/O Module Type	Discrete
Number of Output Points	16
Nominal Output Voltage	12-24 VDC
Discrete Output Type	Sourcing
Number of Isolated Output Commons	2
Number of Points per Common	8
Load Current	0.1A/point
Fuse Type	User-supplied external fuse
Includes	Removable terminal block
Programming Software	CLICK programming software v1.00 or later and CLICK CPU firmware v1.00 or later

## Agency Approvals

UL Listed File #	E157382
UL Recognized File #	None
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>