


# C194 Cut Sheet

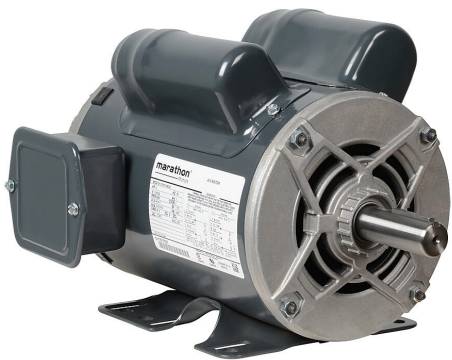

Marathon standard efficiency AC induction motor, general purpose, 3hp, 1-phase, 115/230 VAC, 3600rpm, ODP, NEMA 145T frame, rolled steel, rigid base mount.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/C194>

## Technical Specifications

Brand	Marathon	Shaft Type	Round with square key
Item	Motor	Shaft Diameter	7/8in
Efficiency Group	Standard efficiency	Shaft Material	1144 steel
Efficiency	77	Motor Frame	NEMA 145T
Voltage Type	AC	Frame Material	Rolled steel
Motor Type	Induction	Electrically Reversible	Yes
Motor Application	General purpose	Insulation Class	Class B
Horsepower Rating	3hp	IP Rating	IP22
Number of Phases	1	Service Factor	1.15
Voltage Rating	115/230 VAC	Integrated Brake	No
Synchronous Speed	3600rpm	Junction Box Orientation	F1
Nameplate RPM	3450rpm	Mounting	Rigid base
Overload Type	None	Mounting Orientation	Any
Enclosure Type	ODP	Manufacturer Part Number	5KCR48TN8062

## Agency Approvals

UL Listed File #	None
UL Recognized File #	E46035
UL Hazardous File #	None
CE	None
CSA File #	236833
RoHS Status	No
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/C194.pdf>  
See store item page for other formats.