


# C2-14AR Cut Sheet

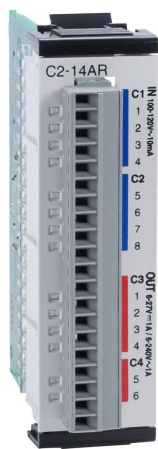

CLICK PLUS discrete combo module, Input: 8-point, 100-120 VAC, Output: 6-point, 6-240 VAC/6-27 VDC, relay, (6) Form A (SPST) relays, 1A/point. Removable terminal block included.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/C2-14AR>

## Technical Specifications

Brand	CLICK PLUS
Item	Combo module
I/O Module Type	Discrete
Number of Input Points	8
Nominal Input Voltage	100-120 VAC
Number of Isolated Discrete Input Commons	2
Number of Points per Discrete Input Common	4
Number of Output Points	6
Nominal Output Voltage	6-240 VAC/6-27 VDC

Discrete Output Type	Relay
Relay Configuration	(6) Form A (SPST) relays
Number of Isolated Discrete Output Commons	2
Number of Points per Discrete Output Common	4/2
Load Current	1A/point
Fuse Type	User-supplied external fuse
Includes	Removable terminal block
Programming Software	CLICK programming software v3.0 or later and CLICK CPU firmware v3.0 or later

## Agency Approvals

UL Listed File #	E157382
UL Recognized File #	None
UL Hazardous File #	None
CE	<a href="#">View CE declarations</a>
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	<a href="#">View EU REACH document</a>

## Dimensional Drawings



2D Drawing PDF Link:  
<https://cdn.automationdirect.com/static/drawings/C2-14AR.pdf>  
See store item page for other formats.