


C6A-CMRSTPBL-S14 Cut Sheet

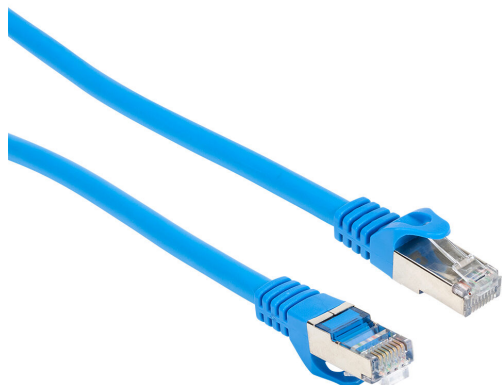

STRIDE Cat6a Ethernet straight-through patch cable, STP (overall foil shield), RJ45 male to RJ45 male, 14ft cable length, blue. For use with 10/100/1000/10000 Mbps networks.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/C6A-CMRSTPBL-S14>

Technical Specifications

Brand	STRIDE
Item	Cable
Cable Type	Cat6a Ethernet straight-through patch
Connection 1	RJ45 male
Connection 2	RJ45 male
Jacket Material	PVC
Jacket Color	Blue
Shield Type	STP (overall foil shield)

UL Rating	UL 444 and UL 1666
UL Wire/Cable Type	CMR
Communication Standard(s)	• IEEE 802.3af PoE • IEEE 802.3at PoE+ • IEEE 802.3bt PoE++
IP Rating	IP20
Cable Length	14ft
For Use With	10/100/1000/10000 Mbps networks

Agency Approvals

UL Listed File #	None
UL Recognized File #	Bare cable: cULus Recognized (E534395) Connector: UL Recognized (E528806)
UL Hazardous File #	None
CE	View CE declarations
CSA File #	None
RoHS Status	Yes (See CE Doc)
EU REACH	View EU REACH document

Dimensional Drawings



2D Drawing PDF Link:
<https://cdn.automationdirect.com/static/drawings/2d/C6A-CMRSTPBL-S14.pdf>
See store item page for other formats.