


CC600-14-4U-1 Cut Sheet

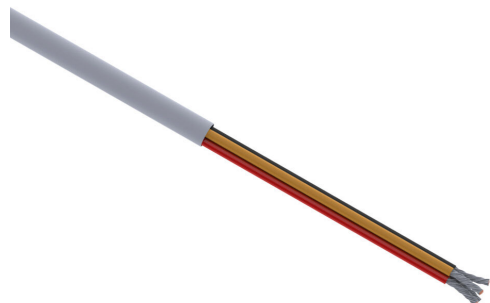

Quabbin control cable, unshielded, 4 conductors, 14 AWG, 41-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CC600-14-4U-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	AWM
Applicable Standards	UL 2586
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V rated (UL)
Conductors	4 conductors
Conductor Size	14 AWG
Conductor Stranding	41-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC

Conductor Insulation Color	Black, brown, red and orange
Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.314in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 99ft = Coil• 100 to 395ft = 14 x 7in Reel• 396 to 565ft = 14 x 10in Reel• 566 to 865ft = 16 x 10in Reel• 866 to 1210ft = 18 x 10in Reel• 1211 to 1575ft = 18 x 13in Reel• 1576 to 3520ft = 24 x 17in Wooden Reel• 3521 to 5000ft = 30 x 17in Wooden Reel

Agency Approvals

UL Listed File #	E69976
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement