


CC600-16-19U-1 Cut Sheet

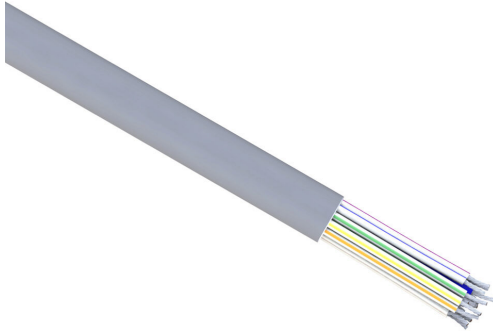

Quabbin control cable, unshielded, 19 conductors, 16 AWG, 19-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CC600-16-19U-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	AWM
Applicable Standards	UL 2586
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V rated (UL)
Conductors	19 conductors
Conductor Size	16 AWG
Conductor Stranding	19-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black, brown, red, orange, yellow, green, blue, violet, gray, white, white/black, white/brown, white/red, white/orange, white/yellow, white/green, white/blue, white/violet and white/gray

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.512in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 150ft = 14 x 7in Reel• 151 to 215ft = 14 x 10in Reel• 216 to 325ft = 16 x 10in Reel• 326 to 455ft = 18 x 10in Reel• 456 to 590ft = 18 x 13in Reel• 591 to 1325ft = 24 x 17in Wooden Reel• 1326 to 2120ft = 30 x 17in Wooden Reel• 2121 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E69976
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement