


CC600-16-5U-1 Cut Sheet

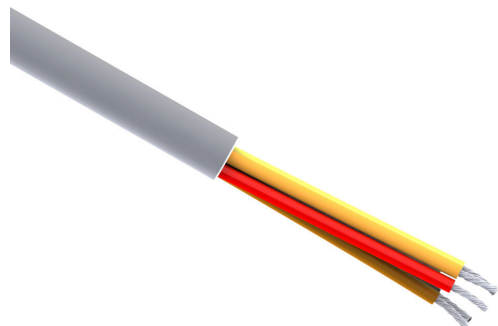

Quabbin control cable, unshielded, 5 conductors, 16 AWG, 19-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CC600-16-5U-1>

Technical Specifications

| | |
|--------------------------------------|--------------------------------------|
| Brand | Quabbin |
| Item | Cable |
| Wire/Cable Type | Control |
| UL Wire/Cable Type | AWM |
| Applicable Standards | UL 2586 |
| Application | General purpose |
| Flexibility | Flexible |
| Voltage Rating | 600V rated (UL) |
| Conductors | 5 conductors |
| Conductor Size | 16 AWG |
| Conductor Stranding | 19-stranded |
| Conductor Material | Tinned copper |
| Conductor Insulation Material | PVC |
| Conductor Insulation Color | Black, brown, red, orange and yellow |

| | |
|---------------------------------------|---|
| Shielding | Unshielded |
| Jacket Material | PVC |
| Jacket Color | Gray |
| Nominal Overall Cable Diameter | 0.307in |
| Bulk Length | Cut to length |
| Package Type | 1 to 50ft = Coil, 51 to 99ft = 14 x 7in Reel, 100 to 402ft = 14 x 10in Reel, 403 to 582ft = 16 x 10in Reel, 583 to 905ft = 18 x 10in Reel, 906 to 1264ft = 18 x 13in Reel, 1265 to 1655ft = 24 x 17in Wooden Reel, 1656 to 3545ft = 30 x 17in Wooden Reel, 3546 to 5000ft = Large Wooden Reel |

Agency Approvals

| | |
|-----------------------------|---|
| UL Listed File # | E69976 |
| UL Recognized File # | None |
| UL Hazardous File # | None |
| CSA File # | LL51726 |
| RoHS Status | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| EU REACH | View EU REACH document |
| Other | RoHS Statement |