


# CC600-16-7U-1 Cut Sheet

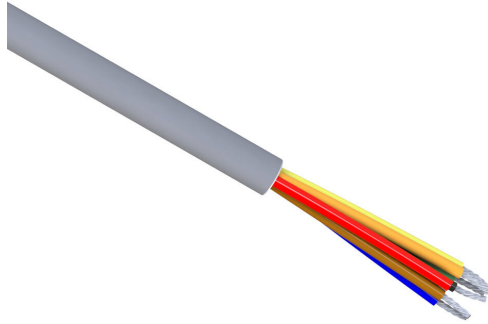

Quabbin control cable, unshielded, 7 conductors, 16 AWG, 19-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CC600-16-7U-1>

## Technical Specifications

|                                      |   |
|--------------------------------------|---|
| <b>Brand</b>                         | Quabbin   |
| <b>Item</b>                          | Cable   |
| <b>Wire/Cable Type</b>               | Control   |
| <b>UL Wire/Cable Type</b>            | AWM   |
| <b>Applicable Standards</b>          | UL 2586   |
| <b>Application</b>                   | General purpose                                   |
| <b>Flexibility</b>                   | Flexible  |
| <b>Voltage Rating</b>                | 600V rated (UL)                                   |
| <b>Conductors</b>                    | 7 conductors                                      |
| <b>Conductor Size</b>                | 16 AWG  |
| <b>Conductor Stranding</b>           | 19-stranded                                       |
| <b>Conductor Material</b>            | Tinned copper                                     |
| <b>Conductor Insulation Material</b> | PVC   |
| <b>Conductor Insulation Color</b>    | Black, brown, red, orange, yellow, green and blue |

|                                       |   |
|---------------------------------------|---|
| <b>Shielding</b>                      | Unshielded  |
| <b>Jacket Material</b>                | PVC   |
| <b>Jacket Color</b>                   | Gray  |
| <b>Nominal Overall Cable Diameter</b> | 0.334in   |
| <b>Bulk Length</b>                    | Cut to length   |
| <b>Package Type</b>                   | <ul style="list-style-type: none"><li>• 20 to 75ft = Coil</li><li>• 76 to 350ft = 14 x 7in Reel</li><li>• 351 to 500ft = 14 x 10in Reel</li><li>• 501 to 765ft = 16 x 10in Reel</li><li>• 766 to 1070ft = 18 x 10in Reel</li><li>• 1071 to 1390ft = 18 x 13in Reel</li><li>• 1391 to 3115ft = 24 x 17in Wooden Reel</li><li>• 3116 to 4980ft = 30 x 17in Wooden Reel</li><li>• 4981 to 5000ft = Large Wooden Reel</li></ul> |

## Agency Approvals

|                             |   |
|-----------------------------|---|
| <b>UL Listed File #</b>     | E69976  |
| <b>UL Recognized File #</b> | None  |
| <b>UL Hazardous File #</b>  | None  |
| <b>CSA File #</b>           | LL51726   |
| <b>RoHS Status</b>          | Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below) |
| <b>EU REACH</b>             | <a href="#">View EU REACH document</a>                              |
| <b>Other</b>                | <a href="#">RoHS Statement</a>                                      |