


CC600-16-9U-1 Cut Sheet

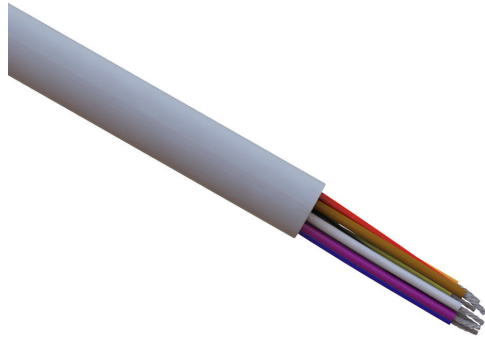

Quabbin control cable, unshielded, 9 conductors, 16 AWG, 19-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CC600-16-9U-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	AWM
Applicable Standards	UL 2586
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V rated (UL)
Conductors	9 conductors
Conductor Size	16 AWG
Conductor Stranding	19-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black, brown, red, orange, yellow, green, blue, violet and gray

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.392in
Bulk Length	Cut to length
Package Type	1 to 50ft = Coil, 51 to 250ft = 14 x 7in Reel, 251 to 360ft = 14 x 10in Reel, 361 to 550ft = 16 x 10in Reel, 551 to 780ft = 18 x 10in Reel, 781 to 1020ft = 18 x 13in Reel, 1021 to 2190ft = 24 x 17in Wooden Reel, 2191 to 3610ft = 30 x 17in Wooden Reel, 3611 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E69976
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement