


CC600-18-25U-1 Cut Sheet

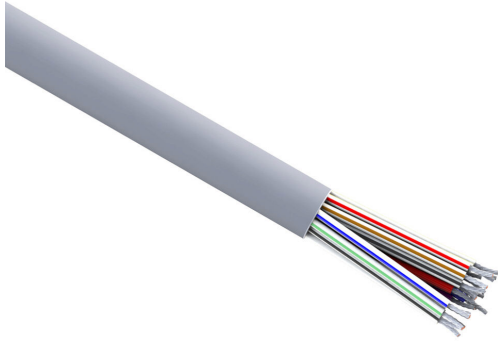

Quabbin control cable, unshielded, 25 conductors, 18 AWG, 16-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CC600-18-25U-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	AWM
Applicable Standards	UL 2586
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V rated (UL)
Conductors	25 conductors
Conductor Size	18 AWG
Conductor Stranding	16-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC
Conductor Insulation Color	Black, brown, red, orange, yellow, green, blue, violet, gray, white, white/black, white/brown, white/red, white/orange, white/yellow, white/green, white/blue, white/violet, white/gray, white/black/brown, white/black/red, white/black/orange, white/black/yellow, white/black/green and white/black/blue

Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.541in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 50ft = Coil• 51 to 135ft = 14 x 7in Reel• 136 to 190ft = 14 x 10in Reel• 191 to 290ft = 16 x 10in Reel• 291 to 410ft = 18 x 10in Reel• 411 to 530ft = 18 x 13in Reel• 531 to 1185ft = 24 x 17in Wooden Reel• 1186 to 1900ft = 30 x 17in Wooden Reel• 1901 to 5000ft = Large Wooden Reel

Agency Approvals

UL Listed File #	E69976
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement