


CC600-18-7U-1 Cut Sheet

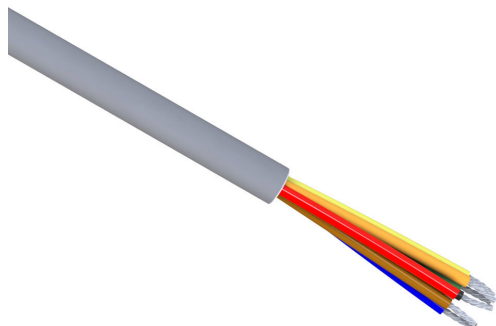

Quabbin control cable, unshielded, 7 conductors, 18 AWG, 16-stranded, tinned copper, PVC conductor insulation material, PVC jacket, gray, cut to length.

For complete product information, please see this item on our store at the following link:



<https://www.automationdirect.com/pn/CC600-18-7U-1>

Technical Specifications

Brand	Quabbin
Item	Cable
Wire/Cable Type	Control
UL Wire/Cable Type	AWM
Applicable Standards	UL 2586
Application	General purpose
Flexibility	Flexible
Voltage Rating	600V rated (UL)
Conductors	7 conductors
Conductor Size	18 AWG
Conductor Stranding	16-stranded
Conductor Material	Tinned copper
Conductor Insulation Material	PVC

Conductor Insulation Color	Black, brown, red, orange, yellow, green and blue
Shielding	Unshielded
Jacket Material	PVC
Jacket Color	Gray
Nominal Overall Cable Diameter	0.298in
Bulk Length	Cut to length
Package Type	<ul style="list-style-type: none">• 20 to 99ft = Coil• 100 to 440ft = 14 x 7in Reel• 441 to 625ft = 14 x 10in Reel• 626 to 960ft = 16 x 10in Reel• 961 to 1345ft = 18 x 10in Reel• 1346 to 1750ft = 18 x 13in Reel• 1751 to 3910ft = 24 x 17in Wooden Reel• 3911 to 5000ft = 30 x 17in Wooden Reel

Agency Approvals

UL Listed File #	E69976
UL Recognized File #	None
UL Hazardous File #	None
CSA File #	LL51726
RoHS Status	Meets RoHS Chemical Restrictions - No CE (See RoHS Statement Below)
EU REACH	View EU REACH document
Other	RoHS Statement